


# P1-04TRS Cut Sheet

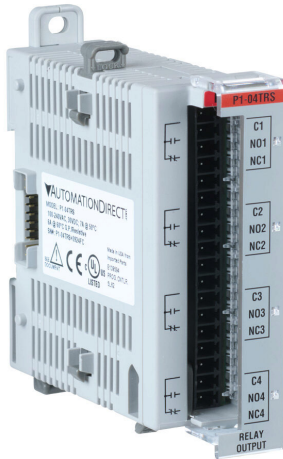

Productivity1000 relay output module, 4-point, 5-30 VDC/5-264 VAC, (4) Form C, 4 isolated common(s), 1 point(s) per common, 7A/point. Requires P2-RTB or P2-RTB-1 removable terminal block.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1-04TRS>

## Technical Specifications

<b>Brand</b>	Productivity1000
<b>Item</b>	Output module
<b>I/O Module Type</b>	Relay
<b>Number of Output Points</b>	4
<b>Nominal Output Voltage</b>	5-30 VDC/5-264 VAC
<b>Relay Configuration</b>	(4) Form C (SPDT) relays
<b>Number of Isolated Commons</b>	4

<b>Jumper Selectable Isolation</b>	No
<b>Number of Points per Common</b>	1
<b>Load Current</b>	7A/point
<b>Fuse Type</b>	User-supplied external fuse
<b>Requires</b>	P2-RTB or P2-RTB-1 removable terminal block
<b>Programming Software</b>	Productivity Suite programming software v4.2 or later

## Agency Approvals

<b>UL Listed File #</b>	E139594
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/P1-04TRS.pdf>  
See store item page for other formats.