


P1-16TR Cut Sheet

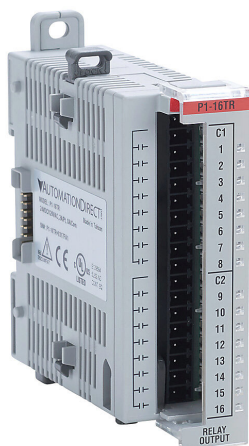

Productivity1000 relay output module, 16-point, 6-24 VDC/6-120 VAC, (16) Form A (SPST) no-suppression, 2 isolated common(s), 8 point(s) per common, 2A/point, 8A/common. Requires P2-RTB or P2-RTB-1 removable terminal block or ZIPLink pre-wired cables.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1-16TR>

Technical Specifications

Brand	Productivity1000
Item	Output module
I/O Module Type	Relay
Number of Output Points	16
Nominal Output Voltage	6-24 VDC/6-120 VAC
Relay Configuration	(16) Form A (SPST) no-suppression relays
Number of Isolated Commons	2
Jumper Selectable Isolation	No
Number of Points per Common	8
Load Current	2A/point, 8A/common
Fuse Type	External fusing 8A max (user supplied)
Requires	P2-RTB or P2-RTB-1 removable terminal block or ZIPLink pre-wired cables
Programming Software	Productivity Suite programming software v3.0 or later

Agency Approvals

UL Listed File #	E139594
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document