


# P1-550 Cut Sheet

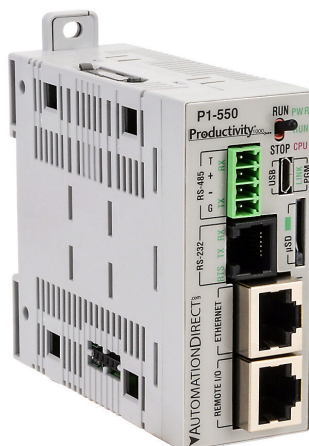

Productivity1000 CPU, up to 50 MB ladder memory, microSD card slot, (2) Ethernet 10/100Base-T (RJ45), (1) RS-232 (RJ12), (1) RS-485 (4-pin terminal) and (1) microB-USB port(s), external 24 VDC required, battery included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1-550>

## Technical Specifications

|  |  |
|--|--|
| <b>Brand</b>                                     | Productivity1000   |
| <b>Item</b>                                      | CPU  |
| <b>Total Memory</b>                              | Up to 50 MB  |
| <b>Ladder Memory</b>                             | Up to 50 MB  |
| <b>User Data Memory</b>                          | Up to 50 MB  |
| <b>Removable Media Type</b>                      | MicroSD card slot  |
| <b>Programming Language</b>                      | Ladder   |
| <b>Programming Software</b>                      | Productivity Suite programming software v3.5 or later  |
| <b>Communication Port and Connection Type(s)</b> | <ul style="list-style-type: none"><li>• (2) Ethernet 10/100Base-T (RJ45)</li><li>• (1) RS-232 (RJ12)</li><li>• (1) RS-485 (4-pin terminal)</li><li>• (1) microB-USB</li></ul>  |
| <b>Port Protocol(s)</b>                          | <ul style="list-style-type: none"><li>• MQTT Client</li><li>• Modbus RTU Master/Slave</li><li>• Modbus TCP</li><li>• ASCII In/out</li><li>• TCP/IP</li><li>• UDP/IP</li><li>• EtherNet/IP explicit messaging scanner/adaptor</li><li>• EtherNet/IP implicit messaging scanner/adaptor</li><li>• Ethernet remote I/O</li><li>• programming and monitoring</li></ul> |

|  |  |
|--|--|
| <b>Port Speed(s)</b>                     | 10/100 Mbps, up to 115.2k baud   |
| <b>Real Time Clock/Calendar</b>          | Yes  |
| <b>Retentive Memory</b>                  | Yes  |
| <b>Battery Backup</b>                    | Yes  |
| <b>Maximum Expansion Modules Allowed</b> | 15   |
| <b>External Power Requirement</b>        | 24 VDC   |
| <b>Includes</b>                          | D2-BAT-1 battery   |
| <b>Dangerous Goods</b>                   | Battery Installed: No, Packaging Instructions: 969, UN Number: UN3091, Hazard Type: Lithium Batteries, Battery Type: Button, Lithium Content: 0.17, Replacement Battery: D2-BAT-1, Generic Battery: CR2354 |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E139594                                |
| <b>UL Recognized File #</b> | None                                   |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | None                                   |
| <b>RoHS Status</b>          | Yes (See CE Doc)                       |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |