


# P1-UX Cut Sheet

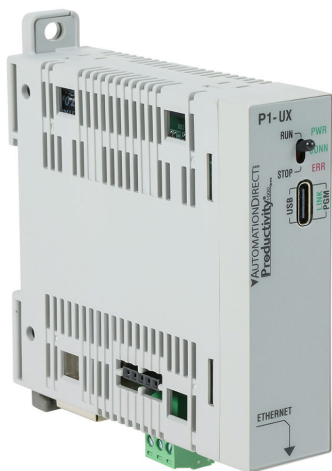

Productivity1000 bus coupler, 24 VDC, (1) Ethernet (RJ45) and (1) USB C port(s), EtherNet/IP and Modbus TCP, 10/100 Mbps. For use with Productivity1000 I/O modules. Supports up to (8) Productivity1000 I/O modules.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1-UX>

## Technical Specifications

|                                           |                                                             |
|-------------------------------------------|-------------------------------------------------------------|
| Brand                                     | Productivity1000                                            |
| Item                                      | Bus coupler                                                 |
| Voltage Rating                            | 24 VDC                                                      |
| Number of Ports                           | 2                                                           |
| Communication Port and Connection Type(s) | (1) Ethernet (RJ45) and (1) USB C port(s)                   |
| Port Protocol(s)                          | EtherNet/IP implicit messaging adapter and Modbus TCP Slave |

|                                   |                                                 |
|-----------------------------------|-------------------------------------------------|
| Port Speed(s)                     | 10/100 Mbps                                     |
| Number of Discrete Inputs/Outputs | 128 inputs/128 outputs                          |
| Number of Analog Inputs/Outputs   | 64 inputs/64 outputs                            |
| For Use With                      | Productivity1000 I/O modules                    |
| Programming Software              | None, configure via Internet browser            |
| Additional Information            | Supports up to (8) Productivity1000 I/O modules |

## Agency Approvals

|                      |                                        |
|----------------------|----------------------------------------|
| UL Listed File #     | E139594                                |
| UL Recognized File # | None                                   |
| UL Hazardous File #  | None                                   |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | None                                   |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/P1-UX.pdf>  
See store item page for other formats.