


P1Y-M1WASFN-100-200 Cut Sheet

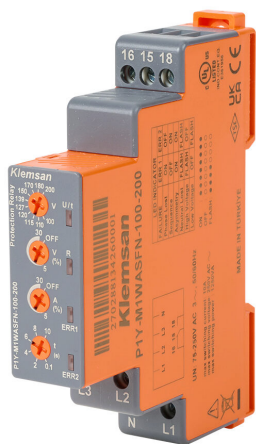

Klemsan phase monitor relay, 3-phase, 35mm DIN rail mount, 75–250 VAC input voltage, SPDT, 10A contact rating, screw terminal(s), LED indicator(s), adjustable settings, phase reversal, phase loss, phase unbalance, over-under voltage and neutral loss protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P1Y-M1WASFN-100-200>

Technical Specifications

Brand	Klemsan
Item	Relay
Relay Type	Phase monitor
Number of Phases	3
Mounting	35mm DIN rail
Relay Housing Type	Finger-safe
Input Voltage	75–250 VAC
Relay Configuration	SPDT
Connector Type	Screw terminal(s)

Contact Rating	10A
Indicator	LED
Setting Type	Adjustable
Protection Type(s)	• phase reversal • phase loss • phase unbalance • over-under voltage • neutral loss

Agency Approvals

UL Listed File #	E542919
UL Recognized File #	NONE
UL Hazardous File #	NONE
CE	View CE declarations
CSA File #	NONE
RoHS Status	Yes with Exemptions (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/P1Y-M1WASFN-100-200.pdf>
See store item page for other formats.