


P2-11B Cut Sheet

Productivity2000 I/O base, 11-slot, DIN rail or flush mount.
Requires P2-01AC, P2-01DCAC or P2-01DC power supply. Holds
power supply, CPU and (11) I/O modules.

For complete product information, please see this item on our
store at the following link:

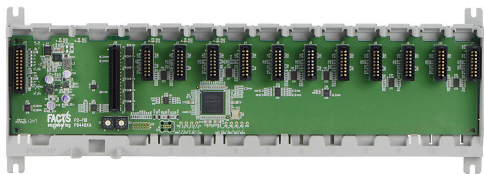

<https://www.automationdirect.com/pn/P2-11B>

Technical Specifications

| | |
|------------------------|---|
| Brand | Productivity2000 |
| Item | I/O base |
| Number Of Slots | 11 |
| Mounting | DIN rail or flush |
| Requires | P2-01AC, P2-01DCAC or P2-01DC power supply |
| Programming Software | Productivity Suite programming software v2.0 or later |
| Additional Information | Holds power supply, CPU and (11) I/O modules |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | E139594 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |
| Other | ABS Certification Document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/P2-11B.pdf>
See store item page for other formats.