


# P2-15B Cut Sheet

Productivity2000 I/O base, 15-slot, DIN rail or flush mount.  
Requires P2-01AC, P2-01DCAC or P2-01DC power supply. Holds power supply, CPU and (15) I/O modules.

For complete product information, please see this item on our store at the following link:

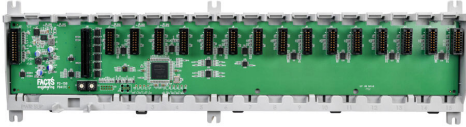

<https://www.automationdirect.com/pn/P2-15B>

---

## Technical Specifications

<b>Brand</b>	Productivity2000
<b>Item</b>	I/O base
<b>Number Of Slots</b>	15
<b>Mounting</b>	DIN rail or flush
<b>Requires</b>	P2-01AC, P2-01DCAC or P2-01DC power supply
<b>Programming Software</b>	Productivity Suite programming software v2.0 or later
<b>Additional Information</b>	Holds power supply, CPU and (15) I/O modules

---

## Agency Approvals

<b>UL Listed File #</b>	E139594
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">ABS Certification Document</a>

---

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/P2-15B.pdf>  
See store item page for other formats.