


P2-SCM Cut Sheet

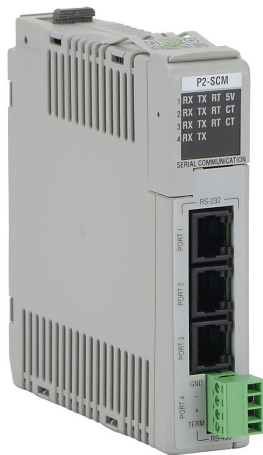

Productivity2000 communication module, Modbus RTU and ASCII, 4 ports, (3) RS-232 (RJ12) and (1) RS-485 (4-pin terminal) port(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/P2-SCM>

Technical Specifications

Brand	Productivity2000
Item	Communication module
Number of Ports	4
Communication Port and Connection Type(s)	<ul style="list-style-type: none">• (3) RS-232 (RJ12)• (1) RS-485 (4-pin terminal)
Port Protocol(s)	<ul style="list-style-type: none">• Modbus RTU• ASCII• custom protocol(s)
Port Speed(s)	up to 38.4k baud
Programming Software	Productivity Suite programming software v2.0 or later

Agency Approvals

UL Listed File #	E139594
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	ABS Certification Document