


PCC-0524-100-00 Cut Sheet

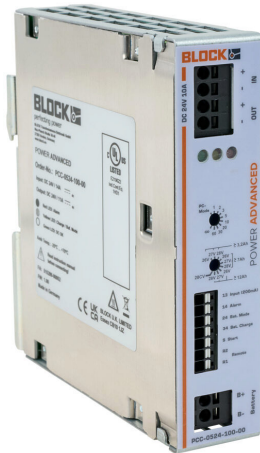

BLOCK battery control module, 1 input, 24 VDC nominal input, 18–30 VDC output, 10A, alarm contact for operation monitoring, push terminals. Requires 24 VDC power supply, battery storage module, batteries.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PCC-0524-100-00>

Technical Specifications

Brand	BLOCK
Item	Battery control module
Number of Inputs	1
Nominal Input Voltage	24 VDC
Input voltage range	18–30 VDC
Nominal Output Voltage	24 VDC
Output Voltage Range	18–30 VDC
Amperage Rating	10A
Protection Type(s)	<ul style="list-style-type: none">• overvoltage• overcurrent

Indicating Type	Output signals for buffering mode, DC OK and Alarm indication
Alarm Contact for Operation Monitoring	Yes
Remote On/Off	Yes
Housing Material	Metal
Mounting	35mm DIN rail
Connector Type	Push terminals
Requires	24 VDC power supply, battery storage module, batteries

Agency Approvals

UL Listed File #	E219022
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/PCC-0524-100-00.pdf>
See store item page for other formats.