


PLTC3-18-4TSS-1 Cut Sheet

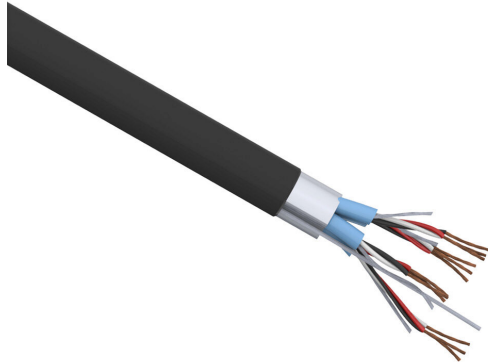

Quabbin instrumentation cable, individual and overall shielded, PLTC and ITC, 300V, 4 twisted triads, 18 AWG, PVC conductor insulation material, black, white and red, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PLTC3-18-4TSS-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Instrumentation
UL Wire/Cable Type	PLTC and ITC
Applicable Standards	UL 2250, UL 1685 and UL 13
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	4 twisted triads
Conductor Size	18 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, white and red

Shielding	Individual and overall shielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.423in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 220ft = 14 x 7in Reel, 221 to 310ft = 14 x 10in Reel, 311 to 475ft = 16 x 10in Reel, 476 to 665ft = 18 x 10in Reel, 666 to 865ft = 18 x 13in Reel, 866 to 1940ft = 24 x 17in Wooden Reel, 1941 to 3105ft = 30 x 17in Wooden Reel, 3106 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E247880,E70148,E118830
UL Recognized File #	E69976
UL Hazardous File #	none
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement