


PLTC3-20-2SS-1 Cut Sheet

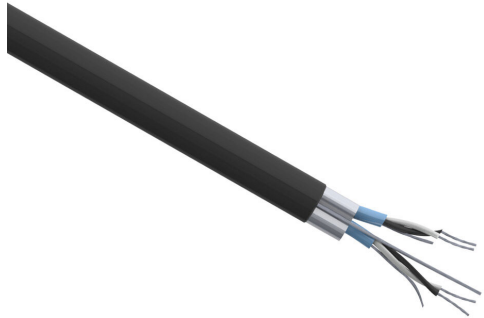

Quabbin instrumentation cable, individual and overall shielded, PLTC, 300V, 2 twisted pairs, 20 AWG, PVC conductor insulation material, black and white numbered pairs, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PLTC3-20-2SS-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Instrumentation
UL Wire/Cable Type	PLTC
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	2 twisted pairs
Conductor Size	20 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black and white numbered pairs

Shielding	Individual and overall shielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.312in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 400ft = 14 x 7in Reel, 401 to 570ft = 14 x 10in Reel, 571 to 875ft = 16 x 10in Reel, 876 to 1225ft = 18 x 10in Reel, 1226 to 1595ft = 18 x 13in Reel, 1596 to 3565ft = 24 x 17in Wooden Reel, 3566 to 5710ft = 30 x 17in Wooden Reel, 5711 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E247880,E70148,E118830
UL Recognized File #	E69976
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement