


PLTC3-20-4SS-1 Cut Sheet

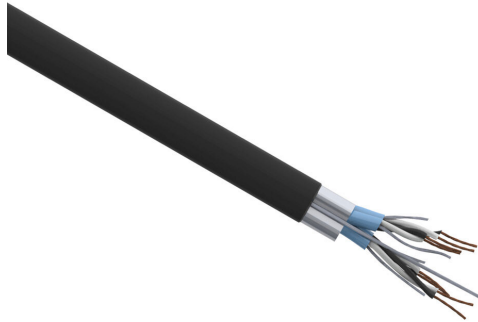

Quabbin instrumentation cable, individual and overall shielded, PLTC, 300V, 4 twisted pairs, 20 AWG, PVC conductor insulation material, black and white numbered pairs, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PLTC3-20-4SS-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Instrumentation
UL Wire/Cable Type	PLTC
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	4 twisted pairs
Conductor Size	20 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black and white numbered pairs

Shielding	Individual and overall shielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.411in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 25 to 50ft = Coil• 51 to 230ft = 14 x 7in Reel• 231 to 330ft = 14 x 10in Reel• 331 to 505ft = 16 x 10in Reel• 506 to 705ft = 18 x 10in Reel• 706 to 920ft = 18 x 13in Reel• 921 to 2055ft = 24 x 17in Wooden Reel• 2056 to 3290ft = 30 x 17in Wooden Reel• 3291 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E247880,E70148,E118830
UL Recognized File #	E69976
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement