


PLTC3-20-8SS-1 Cut Sheet

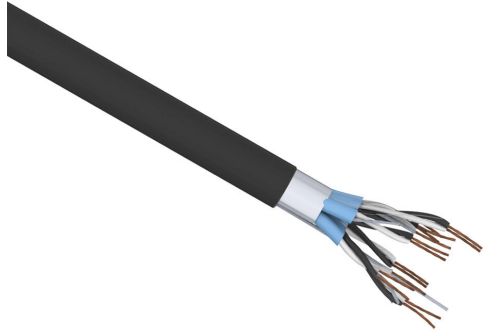

Quabbin instrumentation cable, individual and overall shielded, PLTC, 300V, 8 twisted pairs, 20 AWG, PVC conductor insulation material, black and white numbered pairs, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PLTC3-20-8SS-1>

Technical Specifications

| | |
|--------------------------------------|--------------------------------|
| Brand | Quabbin |
| Item | Cable |
| Wire/Cable Type | Instrumentation |
| UL Wire/Cable Type | PLTC |
| Application | General purpose |
| Flexibility | Semi-flexible |
| Voltage Rating | 300V |
| Conductors | 8 twisted pairs |
| Conductor Size | 20 AWG |
| Conductor Stranding | 7-stranded |
| Conductor Material | Tinned copper |
| Conductor Insulation Material | PVC |
| Conductor Insulation Color | Black and white numbered pairs |

| | |
|---------------------------------------|---|
| Shielding | Individual and overall shielded |
| Jacket Material | PVC |
| Jacket Color | Black |
| Nominal Overall Cable Diameter | 0.52in |
| Bulk Length | Cut to length |
| Package Type | 1 to 50ft = Coil, 51 to 145ft = 14 x 7in Reel, 146 to 205ft = 14 x 10in Reel, 206 to 315ft = 16 x 10in Reel, 316 to 440ft = 18 x 10in Reel, 441 to 575ft = 18 x 13in Reel, 576 to 1285ft = 24 x 17in Wooden Reel, 1286 to 2055ft = 30 x 17in Wooden Reel, 2056 to MAX = Large Wooden Reel |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E247880,E70148,E118830 |
| UL Recognized File # | E69976 |
| UL Hazardous File # | none |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |