


PLTC3-20-8TSS-1 Cut Sheet

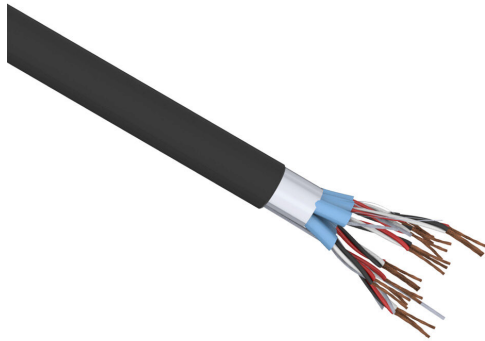

Quabbin instrumentation cable, individual and overall shielded, PLTC and ITC, 300V, 8 twisted triads, 20 AWG, PVC conductor insulation material, black, white and red, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PLTC3-20-8TSS-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Instrumentation
UL Wire/Cable Type	PLTC and ITC
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	8 twisted triads
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, white and red

Shielding	Individual and overall shielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.576in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 120ft = 14 x 7in Reel• 121 to 170ft = 14 x 10in Reel• 171 to 255ft = 16 x 10in Reel• 256 to 360ft = 18 x 10in Reel• 361 to 470ft = 18 x 13in Reel• 471 to 1045ft = 24 x 17in Wooden Reel• 1046 to 1675ft = 30 x 17in Wooden Reel• 1676 to 2500ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E247880,E70148,E118830
UL Recognized File #	E69976
UL Hazardous File #	none
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement