


# PMRRL-1C-240A-TL Cut Sheet

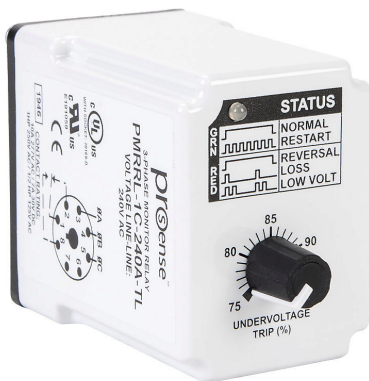

ProSense phase monitor relay, 3-phase, socket mount, 240 VAC input voltage, SPDT, 10A contact rating, 8-pin, LED indicator(s), phase reversal, phase loss and undervoltage protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PMRRL-1C-240A-TL>

## Technical Specifications

Brand	ProSense
Item	Relay
Relay Type	Phase monitor
Number of Phases	3
Mounting	Socket
Relay Housing Type	Finger-safe
Input Voltage	240 VAC
Relay Configuration	SPDT

Connector Type	8-pin
Contact Rating	10A
Indicator	LED
Protection Type(s)	<ul style="list-style-type: none"><li>• phase reversal</li><li>• phase loss</li><li>• undervoltage</li></ul>
Additional Information	Relay becomes UL listed when used with Macromatic 70169-D relay socket

## Agency Approvals

UL Listed File #	E191059
UL Recognized File #	E191059
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/PMRRL-1C-240A-TL.pdf>  
See store item page for other formats.