


PMRRL-1C-240A-TL Cut Sheet

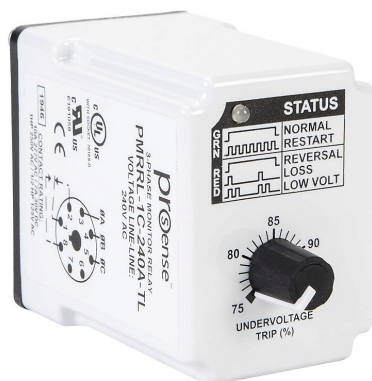

ProSense phase monitor relay, 3-phase, socket mount, finger-safe, 240 VAC input voltage, SPDT, 10A contact rating, 8-pin, LED indicator(s), phase reversal, phase loss and undervoltage protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PMRRL-1C-240A-TL>

Technical Specifications

| | |
|-------------------------------|--|
| Brand | ProSense |
| Item | Relay |
| Relay Type | Phase monitor |
| Number of Phases | 3 |
| Mounting | Socket |
| Relay Housing Type | Finger-safe |
| Input Voltage | 240 VAC |
| Relay Configuration | SPDT |
| Connector Type | 8-pin |
| Contact Rating | 10A |
| Indicator | LED |
| Protection Type(s) | <ul style="list-style-type: none">• phase reversal• phase loss• undervoltage |
| Additional Information | Relay becomes UL listed when used with Macromatic 70169-D relay socket |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E191059 |
| UL Recognized File # | E191059 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |