


# PMTC-12U-3BK-1 Cut Sheet

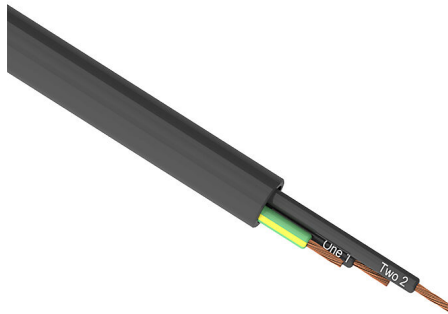

Southwire flexible power/control cable, unshielded, 3 conductors (includes ground), 12 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PMTC-12U-3BK-1>

## Technical Specifications

|                                      |  |
|--------------------------------------|--|
| <b>Brand</b>                         | Southwire  |
| <b>Item</b>                          | Cable  |
| <b>Wire/Cable Type</b>               | Power/control                                    |
| <b>UL Wire/Cable Type</b>            | TC, TC-ER, WTTC and MTW                          |
| <b>Applicable Standards</b>          | ECOLAB   |
| <b>Application</b>                   | General purpose                                  |
| <b>Flexibility</b>                   | Flexible   |
| <b>Voltage Rating</b>                | 600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)   |
| <b>Conductors</b>                    | 3 conductors (includes ground)                   |
| <b>Conductor Size</b>                | 12 AWG   |
| <b>Conductor Stranding</b>           | 65-stranded                                      |
| <b>Conductor Material</b>            | Bare copper                                      |
| <b>Conductor Insulation Material</b> | PVC/Nylon  |
| <b>Conductor Insulation Color</b>    | Black with white numbers and green/yellow ground |

|                                       |   |
|---------------------------------------|---|
| <b>Shielding</b>                      | Unshielded  |
| <b>Jacket Material</b>                | TPE   |
| <b>Jacket Color</b>                   | Black   |
| <b>Nominal Overall Cable Diameter</b> | 0.39in  |
| <b>Bulk Length</b>                    | Cut to length   |
| <b>Package Type</b>                   | <ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 255ft = 14 x 7in Reel</li><li>• 256 to 365ft = 14 x 10in Reel</li><li>• 366 to 560ft = 16 x 10in Reel</li><li>• 561 to 785ft = 18 x 10in Reel</li><li>• 786 to 1020ft = 18 x 13in Reel</li><li>• 1021 to 2285ft = 24 x 17in Wooden Reel</li><li>• 2286 to 3655ft = 30 x 17in Wooden Reel</li><li>• 3656 to 5000ft = Large Wooden Reel</li></ul> |

## Agency Approvals

|                             |   |
|-----------------------------|---|
| <b>UL Listed File #</b>     | E75755  |
| <b>UL Recognized File #</b> | None  |
| <b>UL Hazardous File #</b>  | None  |
| <b>CE</b>                   | None  |
| <b>CSA File #</b>           | 90458   |
| <b>RoHS Status</b>          | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a>                              |
| <b>Other</b>                | <a href="#">RoHS Statement</a>                                      |