


# PSS12-155-U Cut Sheet

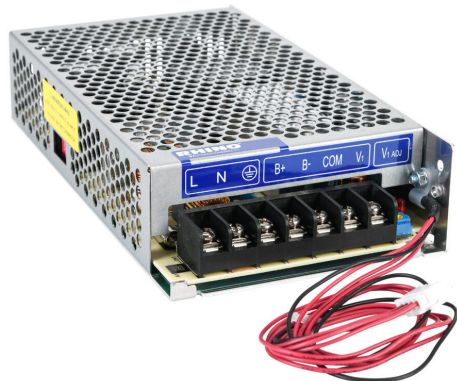

RHINO SELECT PSS series switching power supply, 13.8 VDC @ 11A/151W (adjustable), 120/240 VAC nominal input, 1-phase, enclosed, galvanized steel housing, chassis mount, screw terminals.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PSS12-155-U>

## Technical Specifications

<b>Brand</b>	RHINO SELECT
<b>Item</b>	Power supply
<b>Series</b>	PSS
<b>Power Supply Type</b>	Switching
<b>Efficiency</b>	85% @115 VAC, 86% @230 VAC
<b>Output Configuration</b>	Single output
<b>Output</b>	13.8 VDC @ 11A/151W (adjustable)
<b>Output Voltage Range</b>	12-14 VDC
<b>Input voltage range</b>	85-264 VAC/120-375 VDC
<b>Input Voltage Selection Type</b>	Switch
<b>Number of Input Phases</b>	1
<b>Protection Type(s)</b>	<ul style="list-style-type: none"><li>• overvoltage</li><li>• short circuit</li><li>• overload</li><li>• over-temperature</li></ul>
<b>Remote On/Off</b>	No
<b>Voltage Monitoring</b>	Yes
<b>Enclosure Type</b>	Enclosed
<b>Housing Material</b>	Galvanized steel
<b>IP Rating</b>	IP10
<b>Mounting</b>	Chassis
<b>Connector Type</b>	Screw terminals
<b>NEC Class 2</b>	No
<b>Integrated UPS Battery Control</b>	Yes
<b>Operating Temperature</b>	-20 to 70 deg C

## Agency Approvals

<b>UL Listed File #</b>	E508040
<b>CE</b>	<a href="#">View CE declarations</a>
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>