


# PT14-316NAT100 Cut Sheet

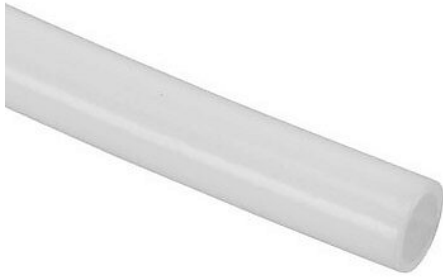

NITRA pneumatic tubing, PTFE, natural, 1/4in outside diameter, 3/16in inside diameter, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PT14-316NAT100>

---

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Tubing
<b>Working Fluid</b>	Air or inert gas
<b>Material</b>	PTFE
<b>Color</b>	Natural
<b>Outside Diameter</b>	1/4in
<b>Inside Diameter</b>	3/16in
<b>Working Length</b>	100ft package
<b>Operating Pressure</b>	174 psi
<b>Operating Temperature</b>	-454 to +500 deg F

---

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>