


# PT6MNAT100 Cut Sheet

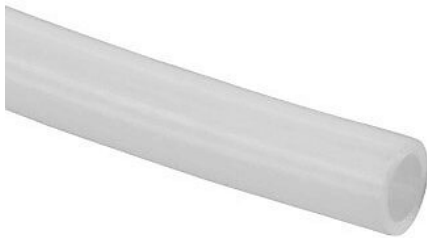

NITRA pneumatic tubing, PTFE, natural, 6mm outside diameter, 5/32in (4mm) inside diameter, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PT6MNAT100>

## Technical Specifications

Brand	NITRA
Item	Tubing
Working Fluid	Air or inert gas
Material	PTFE
Color	Natural
Outside Diameter	6mm
Inside Diameter	5/32in (4mm)
Working Length	100ft package
Operating Pressure	275 psi
Operating Temperature	-454 to +500 deg F

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>