


# PU12MBLU100 Cut Sheet



NITRA pneumatic tubing, ether-based polyurethane, blue, 12mm outside diameter, 5/16in (8mm) inside diameter, 100ft package.

For complete product information, please see this item on our store at the following link:

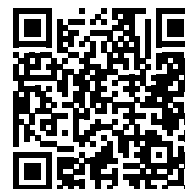

<https://www.automationdirect.com/pn/PU12MBLU100>

---

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Pneumatic Tubing
<b>Material</b>	Ether-based polyurethane
<b>Color</b>	Blue
<b>Outside Diameter</b>	12mm
<b>Inside Diameter</b>	5/16in (8mm)
<b>UV stabilized</b>	No
<b>Working Length</b>	100ft package
<b>Operating Pressure</b>	150 psi
<b>Operating Temperature</b>	-40 to +160 deg F

---

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>