


PU532CBL500 Cut Sheet

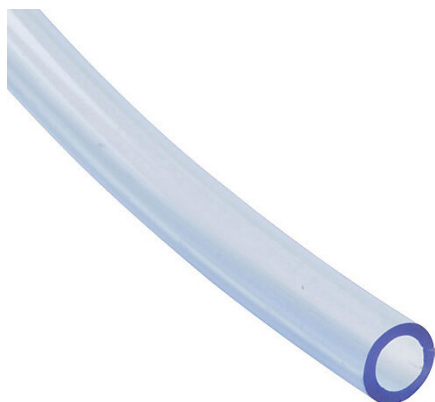

NITRA pneumatic tubing, ether-based polyurethane, clear blue, 5/32in (4mm) outside diameter, 0.093in inside diameter, 500ft reel.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PU532CBL500>

Technical Specifications

Brand	NITRA
Item	Tubing
Working Fluid	Air or inert gas
Material	Ether-based polyurethane
Color	Clear blue
Outside Diameter	5/32in (4mm)
Inside Diameter	0.093in
UV stabilized	No
Working Length	500ft reel
Operating Pressure	200 psi
Operating Temperature	-40 to +160 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document