


PX-148 Cut Sheet

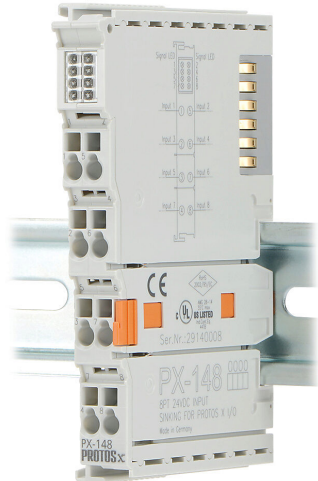

Protos X discrete input module, 8-point, 24 VDC, sinking.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PX-148>

Technical Specifications

Brand	Protos X
Item	Input module
I/O Module Type	Discrete
Number of Input Points	8
Nominal Input Voltage	24 VDC
Discrete Input Type	Sinking
Fast Response	No

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document