


PX-244-1 Cut Sheet

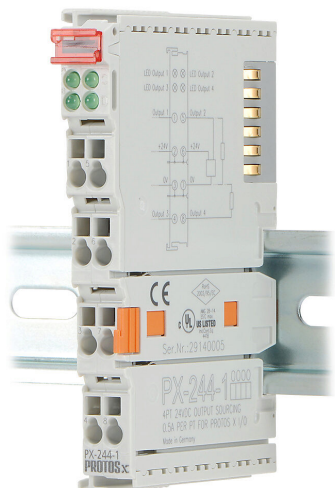

Protos X discrete output module, 4-point, 24 VDC, sourcing, 2 common(s), 2 point(s) per common, 0.5A/point, short circuit and overload protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PX-244-1>

Technical Specifications

Brand	Protos X
Item	Output module
I/O Module Type	Discrete
Number of Output Points	4
Nominal Output Voltage	24 VDC
Discrete Output Type	Sourcing
Number of Non-Isolated Output Commons	2
Number of Points per Common	2
Load Current	0.5A/point
Protection Type(s)	<ul style="list-style-type: none">• short circuit• overload

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document