


# PX-248 Cut Sheet

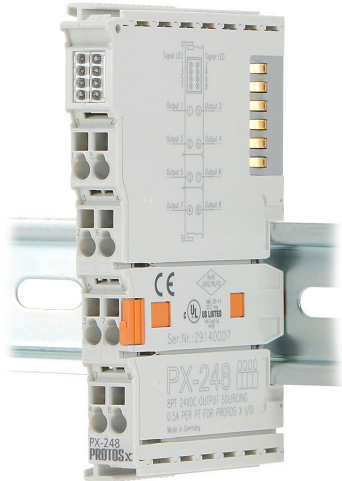

Protos X discrete output module, 8-point, 24 VDC, sourcing, 0.5A/point, short circuit and overload protection.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PX-248>

## Technical Specifications

<b>Brand</b>	Protos X
<b>Item</b>	Output module
<b>I/O Module Type</b>	Discrete
<b>Number of Output Points</b>	8
<b>Nominal Output Voltage</b>	24 VDC
<b>Discrete Output Type</b>	Sourcing
<b>Load Current</b>	0.5A/point
<b>Protection Type(s)</b>	<ul style="list-style-type: none"><li>• short circuit</li><li>• overload</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E157382
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>