


PX-308 Cut Sheet

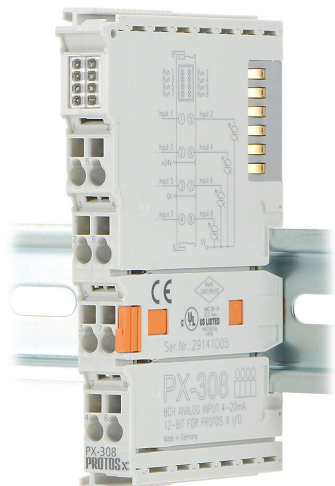

Protos X analog input terminal, 8-channel, current, 12-bit, input current signal range(s) of 4-20 mA, external 24 VDC required.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/PX-308>

Technical Specifications

Brand	Protos X
Item	Input terminal
I/O Module Type	Analog
Number Of Input Channels	8
Input Signal Type(s)	Current
Isolated Channels	No
Input Resolution	12-bit
Input Current Signal Range	4-20 mA
External Power Requirement	24 VDC

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document