


Q0195-1 Cut Sheet

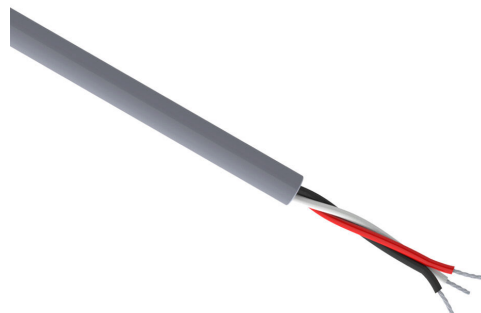

Quabbin control and signal cable, unshielded, 3 conductors, 20 AWG, 10-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q0195-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	PLTC, ITC and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	3 conductors
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Color Code 1
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.224in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 775ft = 14 x 7in Reel, 776 to 1110ft = 14 x 10in Reel, 1111 to 1700ft = 16 x 10in Reel, 1701 to 2380ft = 18 x 10in Reel, 2381 to 3095ft = 18 x 13in Reel, 3096 to 6920ft = 24 x 17in Wooden Reel, 6921 to MAX = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E247880, E69976, E70148
CSA File #	LL66965, LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement