


Q0220-1 Cut Sheet

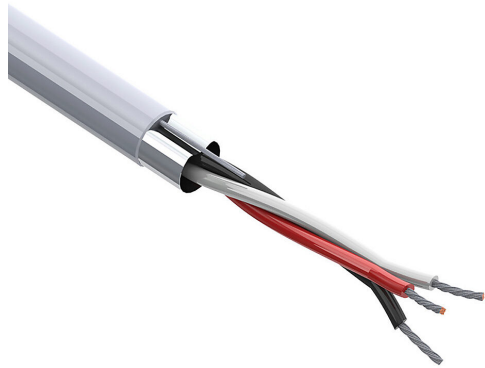

Quabbin control and signal cable, shielded, 3 conductors, 20 AWG, 10-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q0220-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	PLTC, ITC and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	3 conductors
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, white and red

Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.227in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 760ft = 14 x 7in Reel, 761 to 1086ft = 14 x 10in Reel, 1087 to 1681ft = 16 x 10in Reel, 1682 to 2368ft = 18 x 10in Reel, 2369 to 3078ft = 18 x 13in Reel, 3079 to 6612ft = 24 x 17in Wooden Reel, 6613 to 10871ft = 30 x 17in Wooden Reel, 10872 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976,E70148,E247880
CE	None
CSA File #	LL66965
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement