


Q0356-1 Cut Sheet

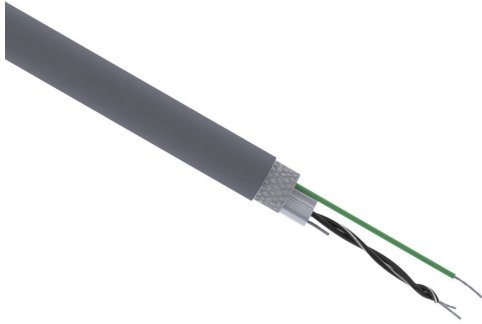

Quabbin RS-422/RS-485 low capacitance data serial cable, shielded, 1.5 twisted pair (includes ground), 24 AWG, 7-stranded, tinned copper, polyethylene conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q0356-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Serial
Wire/Cable Type	RS-422/RS-485 low capacitance data and serial
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2448
Application	Data
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	1.5 twisted pair (includes ground)
Conductor Size	24 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Polyethylene

Conductor Insulation Color	Pair 1: black, black/white and Ground: green
Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.219in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 815ft = 14 x 7in Reel• 816 to 1160ft = 14 x 10in Reel• 1161 to 1780ft = 16 x 10in Reel• 1781 to 2490ft = 18 x 10in Reel• 2491 to 3235ft = 18 x 13in Reel• 3236 to 5000ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E118830, E69976
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement