


Q3100-1 Cut Sheet

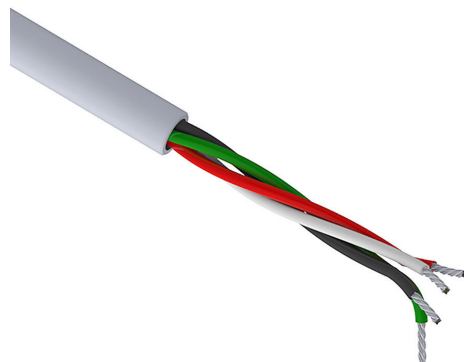

Quabbin control and signal cable, unshielded, 4 conductors, 16 AWG, 19-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q3100-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	CL2 and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	4 conductors
Conductor Size	16 AWG
Conductor Stranding	19-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.279in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 500ft = 14 x 7in Reel, 501 to 719ft = 14 x 10in Reel, 720 to 1113ft = 16 x 10in Reel, 1114 to 1567ft = 18 x 10in Reel, 1568 to 2037ft = 18 x 13in Reel, 2038 to 4377ft = 24 x 17in Wooden Reel, 4378 to 7196ft = 30 x 17in Wooden Reel, 7197 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976,E70148
CE	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement