


Q4120-1 Cut Sheet

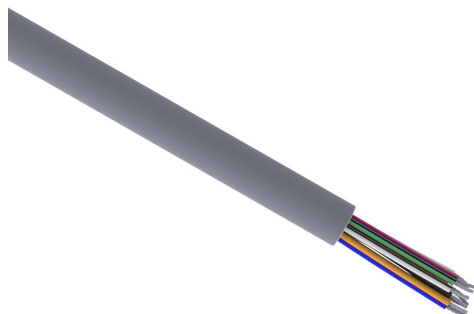

Quabbin control and signal cable, unshielded, 12 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q4120-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	12 conductors
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, white, red, green, orange, blue, white/black, red/black, green/black, orange/black, blue/black and black/white

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.385in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 265ft = 14 x 7in Reel• 266 to 375ft = 14 x 10in Reel• 376 to 575ft = 16 x 10in Reel• 576 to 805ft = 18 x 10in Reel• 806 to 1045ft = 18 x 13in Reel• 1046 to 2345ft = 24 x 17in Wooden Reel• 2346 to 3750ft = 30 x 17in Wooden Reel• 3751 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement