


Q4130-1 Cut Sheet

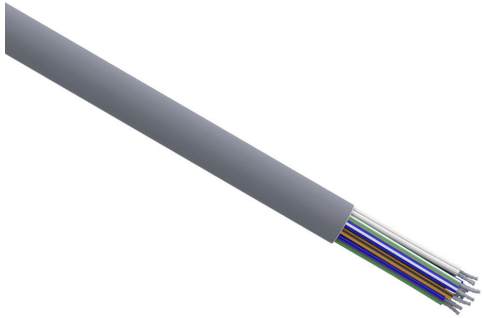

Quabbin control and signal cable, unshielded, 19 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q4130-1>

Technical Specifications

| | |
|--------------------------------------|---|
| Brand | Quabbin |
| Item | Cable |
| Wire/Cable Type | Control and signal |
| UL Wire/Cable Type | CM and AWM |
| Applicable Standards | UL 2464 |
| Application | General purpose |
| Flexibility | Semi-flexible |
| Voltage Rating | 300V |
| Conductors | 19 conductors |
| Conductor Size | 18 AWG |
| Conductor Stranding | 16-stranded |
| Conductor Material | Tinned copper |
| Conductor Insulation Material | PVC |
| Conductor Insulation Color | Black, white, red, green, orange, blue, white/black, red/black, green/black, orange/black, blue/black, black/white, red/white, green/white, blue/white, black/red, white/red, orange/red and blue/red |

| | |
|---------------------------------------|---|
| Shielding | Unshielded |
| Jacket Material | PVC |
| Jacket Color | Gray |
| Nominal Overall Cable Diameter | 0.465in |
| Bulk Length | Cut to length |
| Package Type | <ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 180ft = 14 x 7in Reel• 181 to 260ft = 14 x 10in Reel• 261 to 395ft = 16 x 10in Reel• 396 to 550ft = 18 x 10in Reel• 551 to 720ft = 18 x 13in Reel• 721 to 1605ft = 24 x 17in Wooden Reel• 1606 to 2570ft = 30 x 17in Wooden Reel• 2571 to 5000ft = Large Wooden Reel |

Agency Approvals

| | |
|-------------------------|---|
| UL Listed File # | E118830, E69976 |
| CSA File # | LL51726 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |