


Q4135-1 Cut Sheet

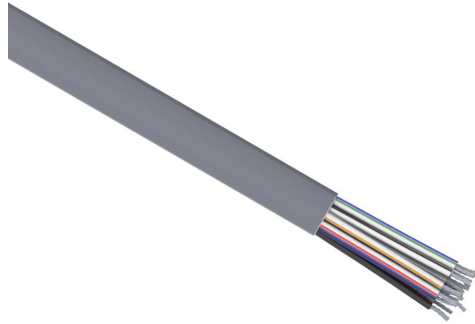

Quabbin control and signal cable, unshielded, 25 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q4135-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	25 conductors
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Color Code 2

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.546in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 130ft = 14 x 7in Reel, 131 to 185ft = 14 x 10in Reel, 186 to 285ft = 16 x 10in Reel, 286 to 400ft = 18 x 10in Reel, 401 to 520ft = 18 x 13in Reel, 521 to 1165ft = 24 x 17in Wooden Reel, 1166 to 1865ft = 30 x 17in Wooden Reel, 1866 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement