


Q4135-1 Cut Sheet

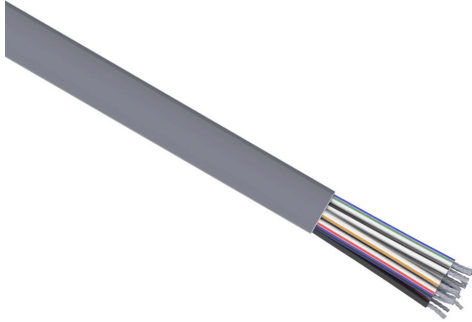

Quabbin control and signal cable, unshielded, 25 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q4135-1>

Technical Specifications

Brand	Quabbin	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Wire/Cable Type	Control and signal	Jacket Color	Gray
UL Wire/Cable Type	CM and AWM	Nominal Overall Cable Diameter	0.546in
Applicable Standards	UL 2464	Bulk Length	Cut to length
Application	General purpose	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 130ft = 14 x 7in Reel• 131 to 185ft = 14 x 10in Reel• 186 to 285ft = 16 x 10in Reel• 286 to 400ft = 18 x 10in Reel• 401 to 520ft = 18 x 13in Reel• 521 to 1165ft = 24 x 17in Wooden Reel• 1166 to 1865ft = 30 x 17in Wooden Reel• 1866 to 5000ft = Large Wooden Reel
Flexibility	Semi-flexible		
Voltage Rating	300V		
Conductors	25 conductors		
Conductor Size	18 AWG		
Conductor Stranding	16-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		
Conductor Insulation Color	Black, white, red, green, orange, blue, white/black, red/black, green/black, orange/black, blue/black, black/white, red/white, green/white, blue/white, black/red, white/red, orange/red, blue/red, red/green, orange/green, black/white/red, white/black/red, red/black/white and green/black/white		

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement