


Q4177-1 Cut Sheet

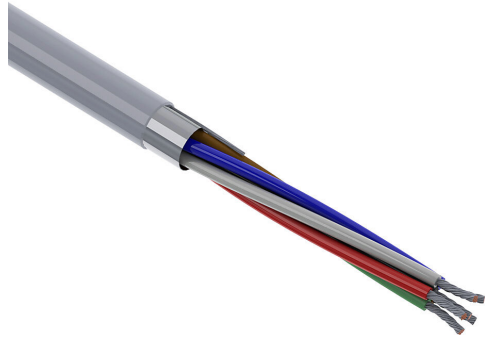

Quabbin control and signal cable, shielded, 6 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q4177-1>

Technical Specifications

| | |
|--------------------------------------|--|
| Brand | Quabbin |
| Item | Cable |
| Wire/Cable Type | Control and signal |
| UL Wire/Cable Type | CM and AWM |
| Applicable Standards | UL 2464 |
| Application | General purpose |
| Flexibility | Semi-flexible |
| Voltage Rating | 300V |
| Conductors | 6 conductors |
| Conductor Size | 18 AWG |
| Conductor Stranding | 16-stranded |
| Conductor Material | Tinned copper |
| Conductor Insulation Material | PVC |
| Conductor Insulation Color | Black, white, red, green, brown and blue |

| | |
|---------------------------------------|--|
| Shielding | Shielded |
| Jacket Material | PVC |
| Jacket Color | Gray |
| Nominal Overall Cable Diameter | 0.259in |
| Bulk Length | Cut to length |
| Package Type | 1 to 99ft = Coil, 100 to 535ft = 14 x 7in Reel, 536 to 584ft = 14 x 10in Reel, 585 to 835ft = 16 x 10in Reel, 836 to 1292ft = 18 x 10in Reel, 1293 to 1819ft = 18 x 13in Reel, 1820 to 2365ft = 24 x 17in Wooden Reel, 2366 to 5079ft = 30 x 17in Wooden Reel, 5080 to MAX = Large Wooden Reel |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E118830 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | LL51726 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |