


Q5094-1 Cut Sheet

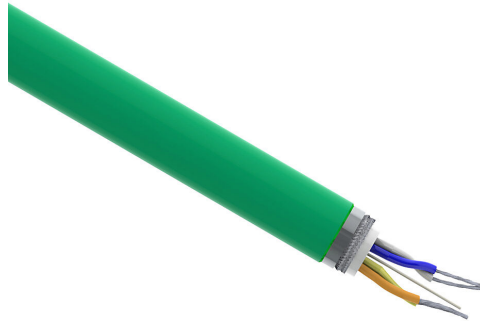

Quabbin continuous flexing Profinet cable, shielded, PLTC and CL3, 4 conductors, 22 AWG, tinned copper, polyethylene conductor insulation material, white, blue, yellow and orange, TPE jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5094-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Fieldbus and ethernet
Wire/Cable Type	Profinet
UL Wire/Cable Type	PLTC and CL3
Applicable Standards	UL 2464
Application	Data
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	4 conductors
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Polyethylene

Conductor Insulation Color	White, blue, yellow and orange
Shielding	Shielded
Jacket Material	TPE
Jacket Color	Green
Nominal Overall Cable Diameter	0.25in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 574ft = 14 x 7in Reel, 575 to 627ft = 14 x 10in Reel, 628 to 896ft = 16 x 10in Reel, 897 to 1387ft = 18 x 10in Reel, 1388 to 1952ft = 18 x 13in Reel, 1953 to 2538ft = 24 x 17in Wooden Reel, 2539 to 5452ft = 30 x 17in Wooden Reel, 5453 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E70148
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement