


Q5099-1 Cut Sheet

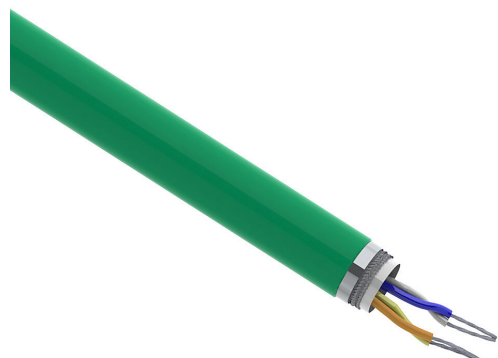

Quabbin continuous flexing Profinet cable, shielded, PLTC-ER and CM, 4 conductors, 22 AWG, tinned copper, polyethylene conductor insulation material, white, blue, yellow and orange, TPE jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5099-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Fieldbus and ethernet
Wire/Cable Type	Profinet
UL Wire/Cable Type	PLTC-ER and CM
Application	Data
Flexibility	Continuous flexing
Voltage Rating	300V
Conductors	4 conductors
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Polyethylene
Conductor Insulation Color	White, blue, yellow and orange

Shielding	Shielded
Jacket Material	TPE
Jacket Color	Green
Nominal Overall Cable Diameter	0.305in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 386ft = 14 x 7in Reel, 387 to 421ft = 14 x 10in Reel, 422 to 602ft = 16 x 10in Reel, 603 to 932ft = 18 x 10in Reel, 933 to 1312ft = 18 x 13in Reel, 1313 to 1705ft = 24 x 17in Wooden Reel, 1706 to 3663ft = 30 x 17in Wooden Reel, 3664 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E70148
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement