


Q5099-1 Cut Sheet

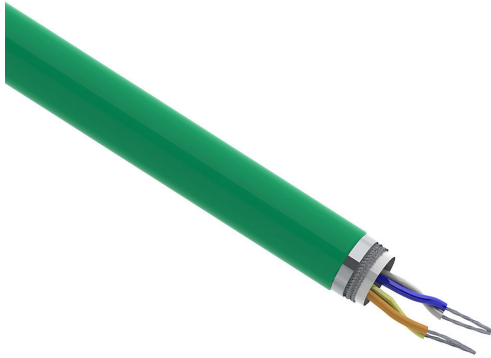

Quabbin continuous flexing Profinet cable, shielded, PLTC-ER and CM, 4 conductors, 22 AWG, tinned copper, polyethylene conductor insulation material, white, blue, yellow and orange, TPE jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5099-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Fieldbus and ethernet
Wire/Cable Type	Profinet
UL Wire/Cable Type	PLTC-ER and CM
Application	Data
Flexibility	Continuous flexing
Voltage Rating	300V
Conductors	4 conductors
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Polyethylene

Conductor Insulation Color	White, blue, yellow and orange
Shielding	Shielded
Jacket Material	TPE
Jacket Color	Green
Nominal Overall Cable Diameter	0.305in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 420ft = 14 x 7in Reel• 421 to 600ft = 14 x 10in Reel• 601 to 920ft = 16 x 10in Reel• 921 to 1285ft = 18 x 10in Reel• 1286 to 1670ft = 18 x 13in Reel• 1671 to 2500ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E70148
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement