


Q5730-1 Cut Sheet

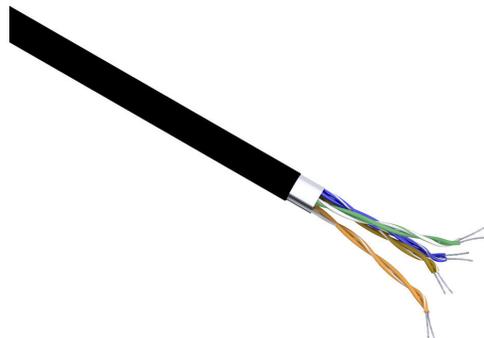

Quabbin Datamax Cat5e industrial Ethernet cable, shielded, 4 twisted pairs, 26 AWG, 7-stranded, tinned copper, polyolefin conductor insulation material, polyurethane jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5730-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Series	Datamax
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
Application	Data
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	4 twisted pairs
Conductor Size	26 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Polyolefin

Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Shielding	Shielded
Jacket Material	Polyurethane
Jacket Color	Black
Nominal Overall Cable Diameter	0.22in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 805ft =14 x 7in Reel• 806 to 1000ft =14 x 10in Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document