


Q5942-1 Cut Sheet

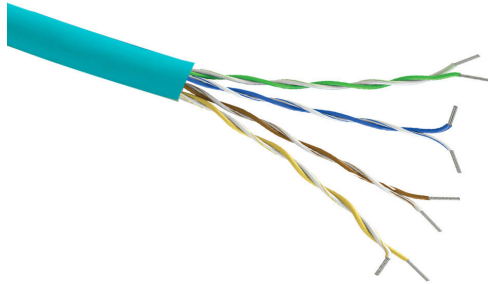

Quabbin Cat5e industrial Ethernet cable, unshielded, 4 twisted pairs, 22 AWG, solid, bare copper, polyethylene conductor insulation material, PVC jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5942-1>

Technical Specifications

Brand	Quabbin	Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Item	Cable	Shielding	Unshielded
Protocol	Ethernet	Jacket Material	PVC
Wire/Cable Type	Cat5e industrial Ethernet	Jacket Color	Teal
UL Wire/Cable Type	CMX, AWM and PLTC	Nominal Overall Cable Diameter	0.267in
Applicable Standards	UL 2463	Bulk Length	Cut to length
Application	Data	Package Type	<ul style="list-style-type: none">• 25 to 99ft = Coil• 100 to 545ft = 14 x 7in Reel• 546 to 780ft = 14 x 10in Reel• 781 to 1200ft = 16 x 10in Reel• 1201 to 1675ft = 18 x 10in Reel• 1676 to 2175ft = 18 x 13in Reel• 2176 to 4870ft = 24 x 17in Wooden Reel• 4871 to 7500ft = 30 x 17in Wooden Reel
Flexibility	Semi-flexible		
Voltage Rating	600V		
Conductors	4 twisted pairs		
Conductor Size	22 AWG		
Conductor Stranding	Solid		
Conductor Material	Bare copper		
Conductor Insulation Material	Polyethylene		

Agency Approvals

UL Listed File #	E118830, E70148, E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement