


Q5942-1 Cut Sheet

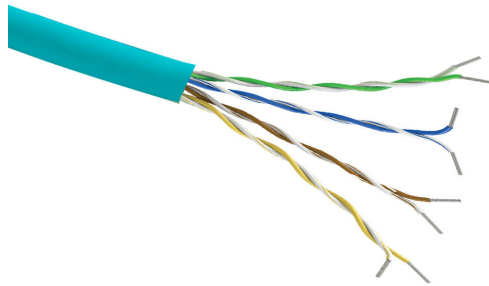

Quabbin Cat5e industrial Ethernet cable, unshielded, 4 twisted pairs, 22 AWG, solid, bare copper, polyethylene conductor insulation material, PVC jacket, teal, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q5942-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	CMX and AWM
Applicable Standards	UL 2463
Application	Data
Flexibility	Semi-flexible
Voltage Rating	600V
Conductors	4 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	Solid
Conductor Material	Bare copper
Conductor Insulation Material	Polyethylene
Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Teal
Nominal Overall Cable Diameter	0.267in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 505ft = 14 x 7in Reel, 506 to 545ft = 14 x 10in Reel, 546 to 775ft = 16 x 10in Reel, 776 to 1200ft = 18 x 10in Reel, 1201 to 1685ft = 18 x 13in Reel, 1686 to 2200ft = 24 x 17in Wooden Reel, 2201 to 4816ft = 30 x 17in Wooden Reel, 4817 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E118830, E70148, E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement