


Q6155-1 Cut Sheet

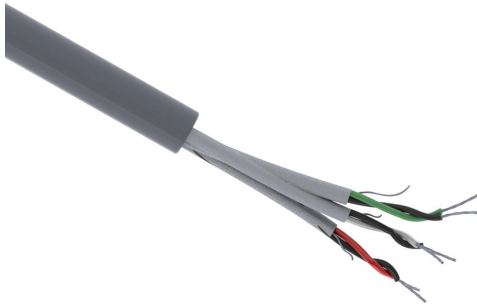

Quabbin serial cable, individual shielded, 3 twisted pairs, 20 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q6155-1>

Technical Specifications

Brand	Quabbin	Conductor Insulation Color	Pair 1: black, red, pair 2: black, white and pair 3: black, green
Item	Cable	Shielding	Individual shielded
Protocol	Serial	Jacket Material	PVC
Wire/Cable Type	Serial	Jacket Color	Gray
UL Wire/Cable Type	CM and AWM	Nominal Overall Cable Diameter	0.325in
Applicable Standards	UL 2919	Bulk Length	Cut to length
Application	Data	Package Type	<ul style="list-style-type: none">• 25 to 75ft = Coil• 76 to 370ft = 14 x 7in Reel• 371 to 525ft = 14 x 10in Reel• 526 to 810ft = 16 x 10in Reel• 811 to 1130ft = 18 x 10in Reel• 1131 to 1470ft = 18 x 13in Reel• 1471 to 3290ft = 24 x 17in Wooden Reel• 3291 to 5000ft = 30 x 17in Wooden Reel
Flexibility	Semi-flexible		
Voltage Rating	300V		
Conductors	3 twisted pairs		
Conductor Size	20 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		

Agency Approvals

UL Listed File #	E118830
UL Recognized File #	E69976
UL Hazardous File #	None
CE	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement