


Q7160-1 Cut Sheet

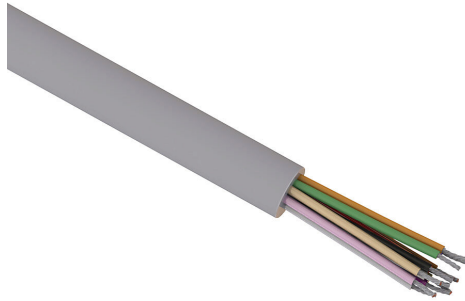

Quabbin control and signal cable, unshielded, 12 conductors, 22 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q7160-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	12 conductors
Conductor Size	22 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, red, white, green, orange, blue, brown, yellow, violet, gray, pink and tan

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.266in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 507ft = 14 x 7in Reel, 508 to 554ft = 14 x 10in Reel, 555 to 791ft = 16 x 10in Reel, 792 to 1225ft = 18 x 10in Reel, 1226 to 1725ft = 18 x 13in Reel, 1726 to 2242ft = 24 x 17in Wooden Reel, 2243 to 4816ft = 30 x 17in Wooden Reel, 4817 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E118830
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement