


Q7380-1 Cut Sheet

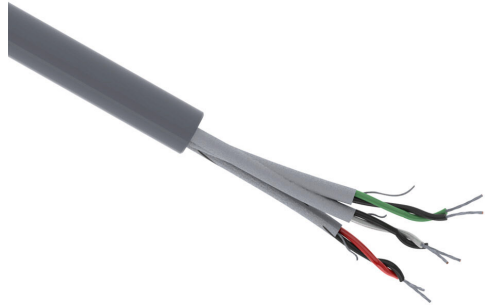

Quabbin serial cable, individual shielded, 3 twisted pairs, 22 AWG, solid, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q7380-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Protocol	Serial
Wire/Cable Type	Serial
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2464
Application	Data
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	3 twisted pairs
Conductor Size	22 AWG
Conductor Stranding	Solid
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Pair 1: black, red, pair 2: black, white and pair 3: black, green
Shielding	Individual shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.27in
Bulk Length	Cut to length

Agency Approvals

UL Listed File #	E118830
UL Recognized File #	E69976
UL Hazardous File #	None
CE	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement