


# Q7380-1 Cut Sheet

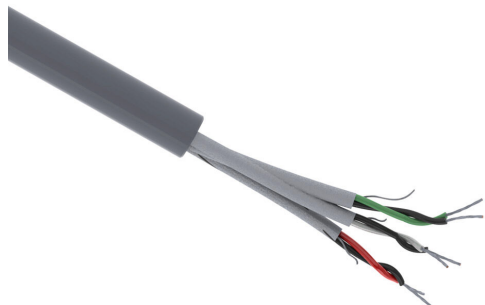

Quabbin serial cable, individual shielded, 3 twisted pairs, 22 AWG, solid, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q7380-1>

## Technical Specifications

<b>Brand</b>	Quabbin
<b>Item</b>	Cable
<b>Protocol</b>	Serial
<b>Wire/Cable Type</b>	Serial
<b>UL Wire/Cable Type</b>	CM and AWM
<b>Applicable Standards</b>	UL 2464
<b>Application</b>	Data
<b>Flexibility</b>	Semi-flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	3 twisted pairs
<b>Conductor Size</b>	22 AWG
<b>Conductor Stranding</b>	Solid
<b>Conductor Material</b>	Tinned copper
<b>Conductor Insulation Material</b>	PVC

<b>Conductor Insulation Color</b>	Pair 1: black, red, pair 2: black, white and pair 3: black, green
<b>Shielding</b>	Individual shielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Gray
<b>Nominal Overall Cable Diameter</b>	0.27in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 25 to 99ft = Coil</li><li>• 100 to 535ft = 14 x 7in Reel</li><li>• 536 to 765ft = 14 x 10in Reel</li><li>• 766 to 1170ft = 16 x 10in Reel</li><li>• 1171 to 1640ft = 18 x 10in Reel</li><li>• 1641 to 2130ft = 18 x 13in Reel</li><li>• 2131 to 4765ft = 24 x 17in Wooden Reel</li><li>• 4766 to 5000ft = 30 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E118830
<b>UL Recognized File #</b>	E69976
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	LL51726
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>