


Q7545-1 Cut Sheet

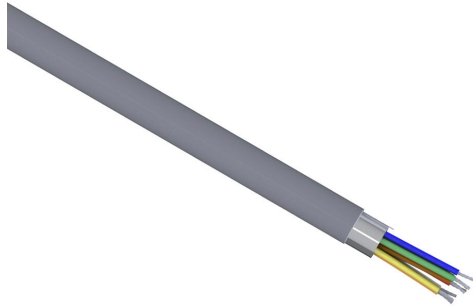

Quabbin control and signal cable, shielded, 8 conductors, 22 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q7545-1>

Technical Specifications

Brand	Quabbin	Conductor Insulation Color	Black, white, red, green, orange, brown, blue and yellow
Item	Cable	Shielding	Shielded
Wire/Cable Type	Control and signal	Jacket Material	PVC
UL Wire/Cable Type	CM and AWM	Jacket Color	Gray
Applicable Standards	UL 2464	Nominal Overall Cable Diameter	0.242in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Semi-flexible	Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 665ft = 14 x 7in Reel• 666 to 950ft = 14 x 10in Reel• 951 to 1460ft = 16 x 10in Reel• 1461 to 2040ft = 18 x 10in Reel• 2041 to 2650ft = 18 x 13in Reel• 2651 to 5000ft = 24 x 17in Wooden Reel
Voltage Rating	300V		
Conductors	8 conductors		
Conductor Size	22 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement