


Q8195-1 Cut Sheet

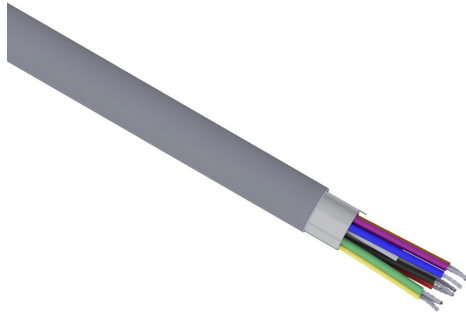

Quabbin control and signal cable, shielded, 9 conductors, 24 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q8195-1>

Technical Specifications

Brand	Quabbin	Conductor Insulation Color	Black, white, red, green, orange, brown, blue, yellow and purple
Item	Cable	Shielding	Shielded
Wire/Cable Type	Control and signal	Jacket Material	PVC
UL Wire/Cable Type	CM and AWM	Jacket Color	Gray
Applicable Standards	UL 2464	Nominal Overall Cable Diameter	0.253in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Semi-flexible	Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 610ft = 14 x 7in Reel• 611 to 870ft = 14 x 10in Reel• 871 to 1335ft = 16 x 10in Reel• 1336 to 1865ft = 18 x 10in Reel• 1866 to 2425ft = 18 x 13in Reel• 2426 to 5000ft = 24 x 17in Wooden Reel
Voltage Rating	300V		
Conductors	9 conductors		
Conductor Size	24 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement