


Q8205-1 Cut Sheet

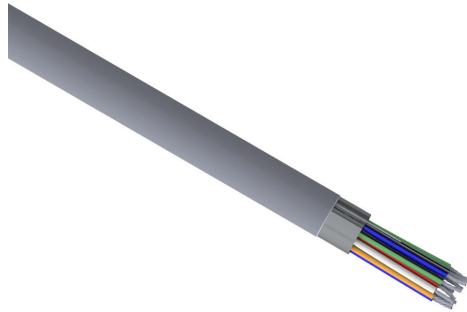

Quabbin control and signal cable, shielded, 15 conductors, 24 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/Q8205-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	CM and AWM
Applicable Standards	UL 2464
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	300V
Conductors	15 conductors
Conductor Size	24 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Color Code 2

Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.28in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 495ft = 14 x 7in Reel, 496 to 710ft = 14 x 10in Reel, 711 to 1090ft = 16 x 10in Reel, 1091 to 1525ft = 18 x 10in Reel, 1526 to 1980ft = 18 x 13in Reel, 1981 to 4430ft = 24 x 17in Wooden Reel, 4431 to 7085ft = 30 x 17in Wooden Reel, 7086 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E118830, E69976
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement