


# RK7815-71-61 Cut Sheet

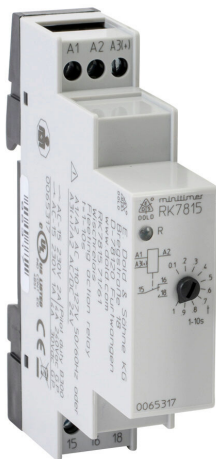

Dold fleeting (single-shot) relay timer, 1 to 10 seconds timing range, 24 VAC/VDC and 110-127 VAC operating voltage, 2A contact rating, (1) SPDT timed relay output(s), 35mm DIN rail mount, screw terminal(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RK7815-71-61>

## Technical Specifications

Brand	Dold
Item	Relay timer
Timer Type	Fleeting (single-shot)
Indicator	LED
Timing Range	1 to 10 seconds
Operating Voltage	24 VAC/VDC and 110-127 VAC
Timer Output Type(s)	(1) SPDT timed relay
Timer Function(s)	fleeting (single-shot)
Contact Rating	2A
Mounting	35mm DIN rail
Connector Type	Screw terminal(s)

## Agency Approvals

UL Listed File #	E107778
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/RK7815-71-61.pdf>  
See store item page for other formats.