


RTD1-C06-02 Cut Sheet

ProSense temperature sensor, Pt100 RTD, connection head probe, 6in insertion length, 1/4in probe diameter, stainless steel sheath, aluminum screw cover head with terminals.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/RTD1-C06-02>

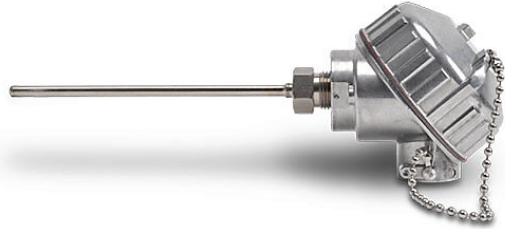

Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Pt100 RTD
Sensor Type	Connection head probe
Accuracy	Class A accuracy
Insertion Length	6in
Probe Diameter	1/4in
Sheath Material	Stainless steel
Sensor Insulation	Alumina powder
Electrical Connection	Aluminum screw cover head with terminals
Temperature Sensing Range	-58 to 572 deg F
Additional Information	Purchase mounting fitting separately

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document